
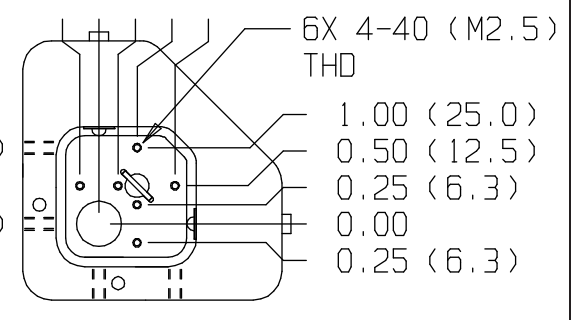
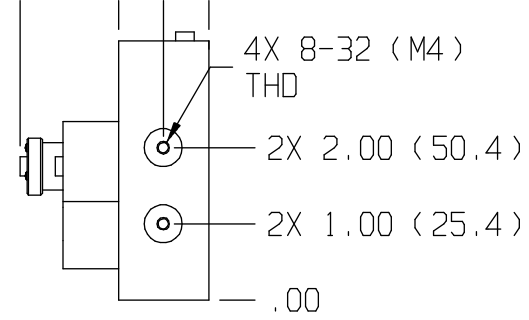


3.40 (86.5)
 1.25 (31.8)
 1.00 (25.4)
 0.22 (5.5)
 .00

2.48 (63.0)
 1.19 (30.2)
 0.59 (15.1)
 0.00

0.25 (6.3)
 0.00
 0.25 (6.3)
 0.50 (12.5)
 1.00 (25.0)

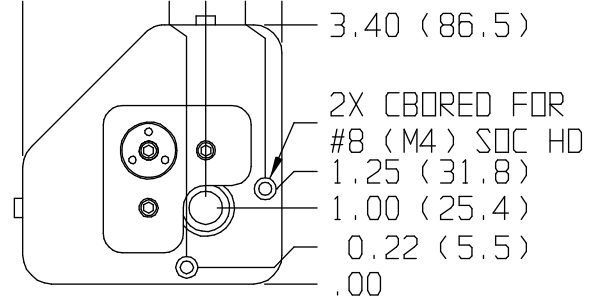

9091(M) FIBER ALIGNER

