


Filter: T1Q01

Color: Green
Material: Glass
VLT: 35%



Optical Density (OD):

- 690 - 795 DIRM LB7 (OD 7+)
- >795 - 1100 DIR LB7 + M LB9 (OD 9+)
- >1100 - 1200 DIR LB7 + M LB8 (OD 8+)
- >1200 - 1320 DIRM LB7 (OD 7+)
- >1320 - 1400 DIRM LB3 (OD 3+)
- >1400 - 1550 DIR LB3 (OD 3+)
- 10600 DI LB4 (OD 4+)
- 0,1W 2*10-5J 633 RB2 (OD 2-3)
- LVU CE

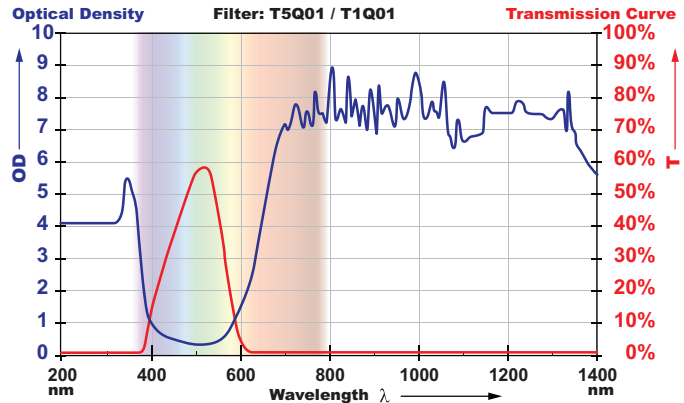

Visual interpretation of data. Please refer to the OD specifications for the actual protection level.




R14.T1Q01.5000




Labels

R14.T1Q01.5000

690 - 795 DIRM LB7 (OD 7+)
 >795 - 1100 DIR LB7 + M LB9 (OD 9+)
 >1100 - 1200 DIR LB7 + M LB8 (OD 8+)
 >1200 - 1320 DIRM LB7 (OD 7+)
 >1320 - 1400 DIRM LB3 (OD 3+)
 >1400 - 1550 DIR LB3 (OD 3+)
 10600 DI LB4 (OD 4+)
 0,1W 2*10-5J 633 RB2 (OD 2-3)
 LVU CE


  MM/YYYY
VLT 35%

Manufactured by:
 LASERVISION USA, LP
 595 Phalen Boulevard,
 Saint Paul, MN 55130
 info@lasersafety.com | lasersafety.com
 P 800-393-5565

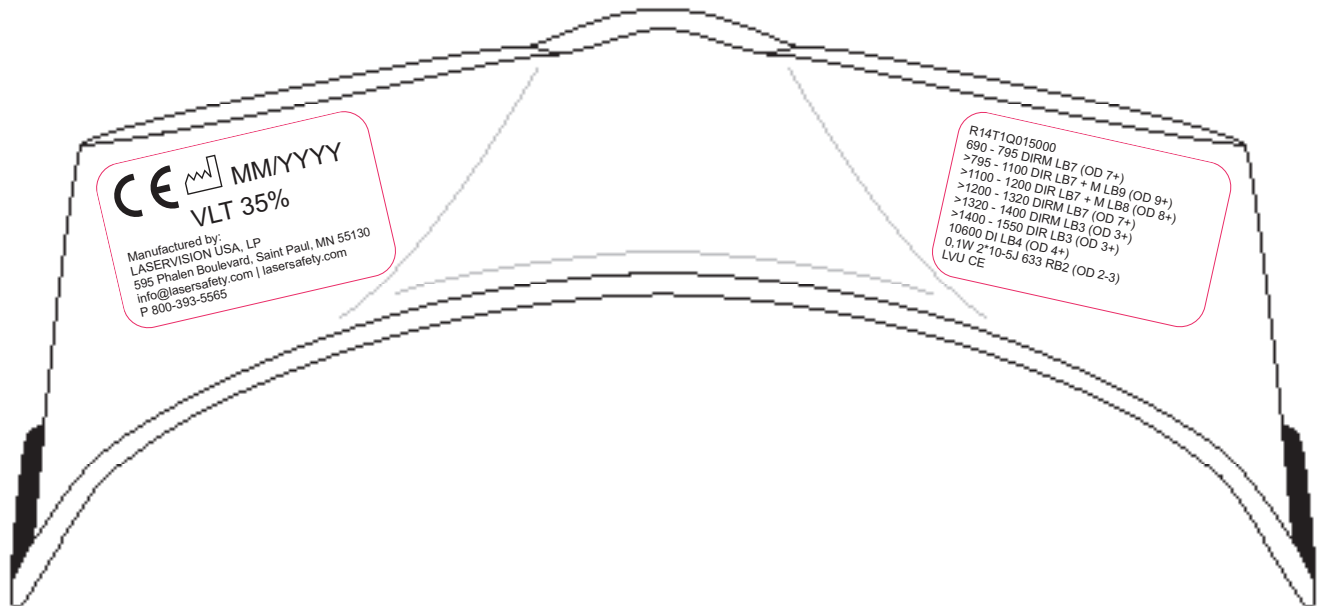

Contact: Tom Poole
 t.poole@lasersafety.com
 Phone: 651-357-1801

 Authorized Customer Signature

 Date

 Authorized Laservision Signature

 Date