


4 X 1/4-20 (M6) Counterbored
 Ø .281 THRU ALL
 ▬ Ø.44 ▾ .26

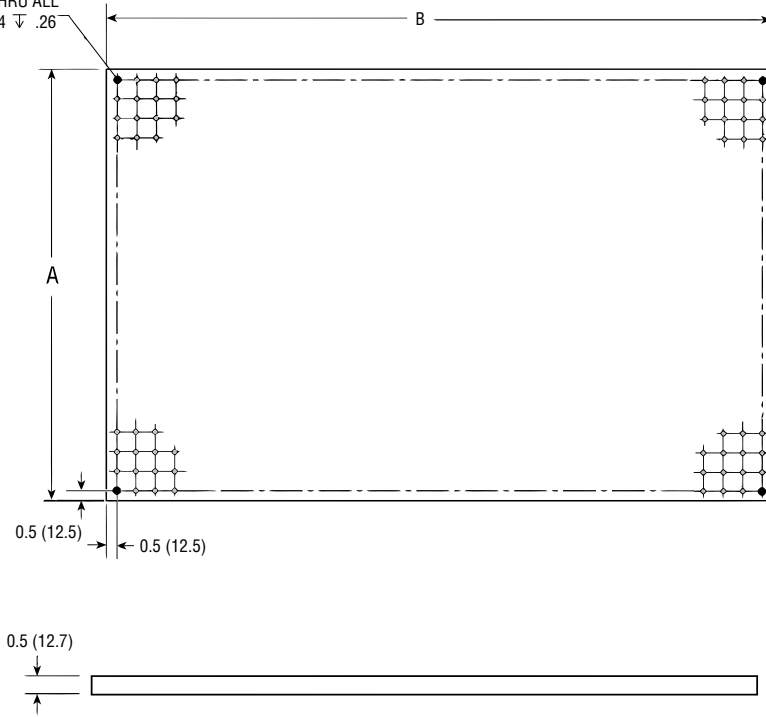

Model	A	B	Mounting Holes
(-LC version has same values)			
M-SA2-04X06	100 mm.	150 mm.	M6
M-SA2-04X12	100 mm.	300 mm.	M6
M-SA2-06X06	150 mm.	150 mm.	M6
M-SA2-06X12	150 mm.	300 mm.	M6
M-SA2-06X18	150 mm.	450 mm.	M6
M-SA2-06x24	150 mm.	600 mm.	M6

M-SA2-06x36	150 mm.	900 mm.	M6
M-SA2-08X08	200 mm.	200 mm.	M6
M-SA2-08X10	200 mm.	250 mm.	M6
M-SA2-10X12	250 mm.	300 mm.	M6
M-SA2-11	300 mm.	300 mm.	M6
M-SA2-12	300 mm.	600 mm.	M6
M-SA2-12X18	300 mm.	450 mm.	M6
M-SA2-13	300 mm.	900 mm.	M6
M-SA2-18X18	450 mm.	450 mm.	M6
M-SA2-18X24	450 mm.	600 mm.	M6
M-SA2-18X30	450 mm.	750 mm.	M6
M-SA2-18X36	450 mm.	900 mm.	M6
M-SA2-22	600 mm.	600 mm.	M6
M-SA2-23	600 mm.	900 mm.	M6
M-SA2-24	600 mm.	1200 mm.	M6
M-SA2-30X30	600 mm.	600 mm.	M6
SA2-04x06	4 in.	6 in.	1/4-20
SA2-04X12	4 in.	12 in.	1/4-20
SA2-06x06	6 in.	6 in.	1/4-20
SA2-06X12	6 in.	12 in.	1/4-20
SA2-06X18	6 in.	18 in.	1/4-20
SA2-06x24	6 in.	24 in.	1/4-20
SA2-06x36	6 in.	36 in.	1/4-20
SA2-08X08	8 in.	8 in.	1/4-20
SA2-08X10	8 in.	10 in.	1/4-20
SA2-10X12	10 in.	12 in.	1/4-20
SA2-11	12 in.	12 in.	1/4-20
SA2-12	12 in.	24 in.	1/4-20
SA2-12X18	12 in.	18 in.	1/4-20
SA2-13	12 in.	36 in.	1/4-20
SA2-18X18	18 in.	18 in.	1/4-20
SA2-18X24	18 in.	24 in.	1/4-20
SA2-18X30	18 in.	30 in.	1/4-20
SA2-18X36	18 in.	36 in.	1/4-20
SA2-22	24 in.	24 in.	1/4-20
SA2-23	24 in.	36 in.	1/4-20
SA2-24	24 in.	48 in.	1/4-20
SA2-30X30	30 in.	30 in.	1/4-20