


DIFFRACTION GRATING SPECIFICATION SHEET

Catalog no.	53-*-530R	3/10/2020
Grating Description	1200 g/mm plane ruled reflection grating with 36.8° nominal blaze angle	
Master no.	1113	
Maximum Ruled Area:		
	groove length	154 mm
	ruled width:	206 mm

Efficiency Curve	spectral order:	m = 1	polarization(s):	S and P
	Coating:	aluminum		
Remarks:				

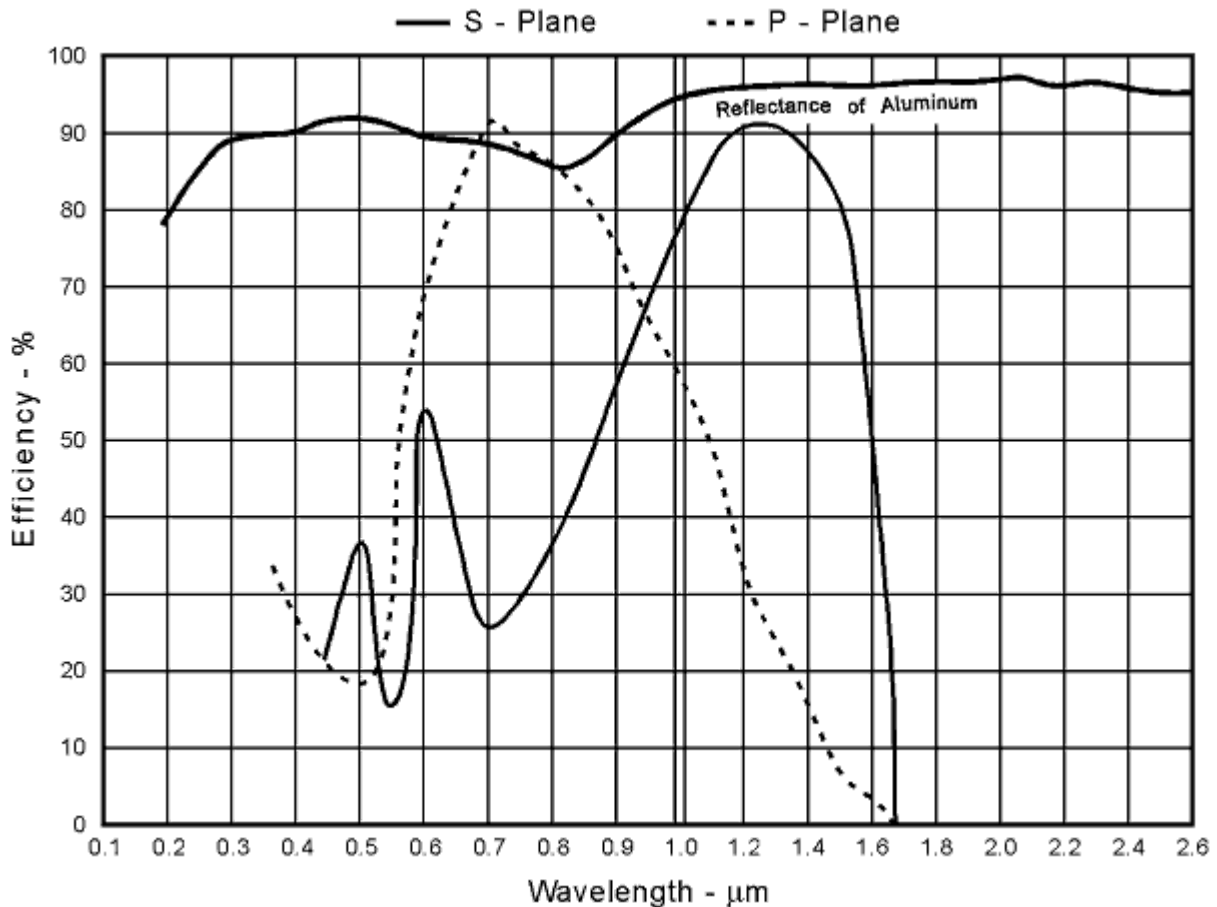

Note: The efficiency curve above is relative (not absolute) and was measured in an in-plane near Littrow configuration (unless otherwise indicated). Efficiency curves are only representative: actual efficiency may vary significantly depending on use geometry and measurement technique. This efficiency curve is for master 1113; two masters with the same catalog number may have different efficiency curves. The uncertainty band on the data in the above efficiency curve(s) is +/- three percentage points.