


DIFFRACTION GRATING SPECIFICATION SHEET

Catalog no.	53-*-201R	3/10/2020
Grating Description	150 g/mm plane ruled reflection grating with 2.2° nominal blaze angle	
Master no.	1055	
Maximum Ruled Area:		groove length
		ruled width:
		102 mm
		128 mm

Efficiency Curve	spectral order:	m = 1	polarization(s):	Unpolarized
	Coating:	aluminum		
Remarks:				

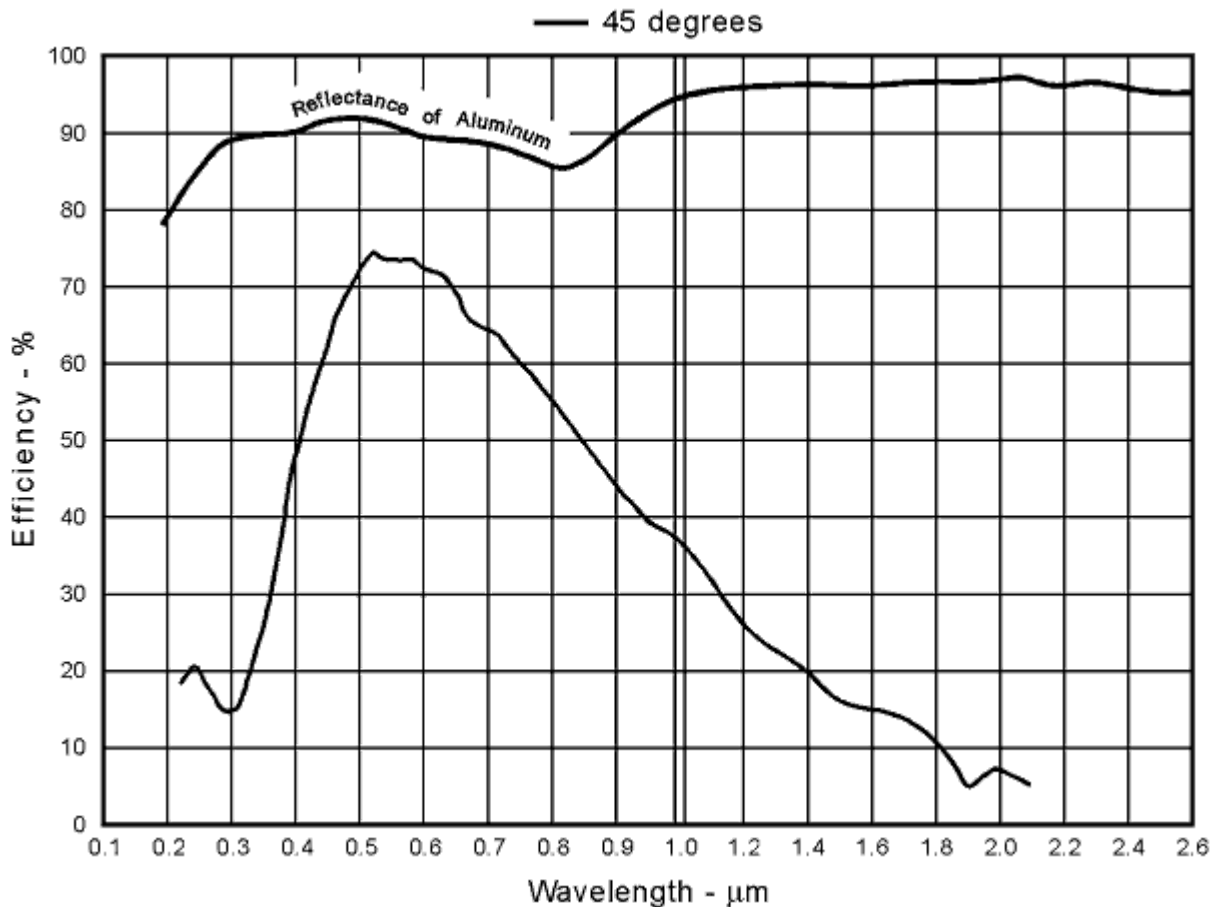

Note: The efficiency curve above is relative (not absolute) and was measured in an in-plane near Littrow configuration (unless otherwise indicated). Efficiency curves are only representative: actual efficiency may vary significantly depending on use geometry and measurement technique. This efficiency curve is for master 1055; two masters with the same catalog number may have different efficiency curves. The uncertainty band on the data in the above efficiency curve(s) is +/- three percentage points.