
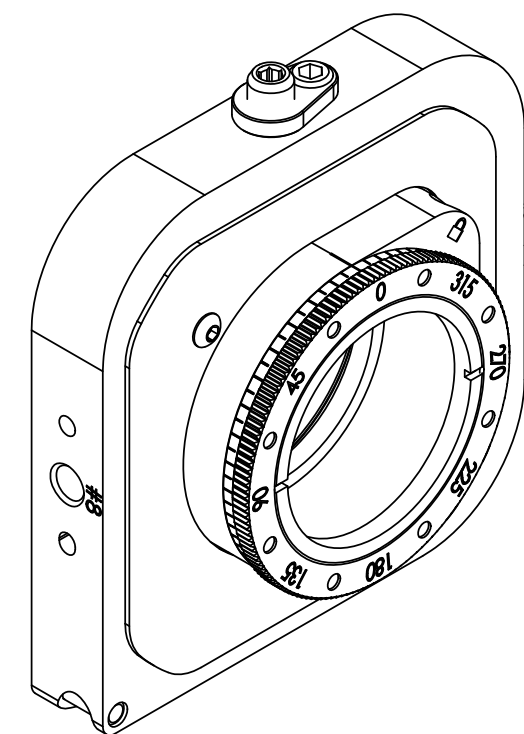
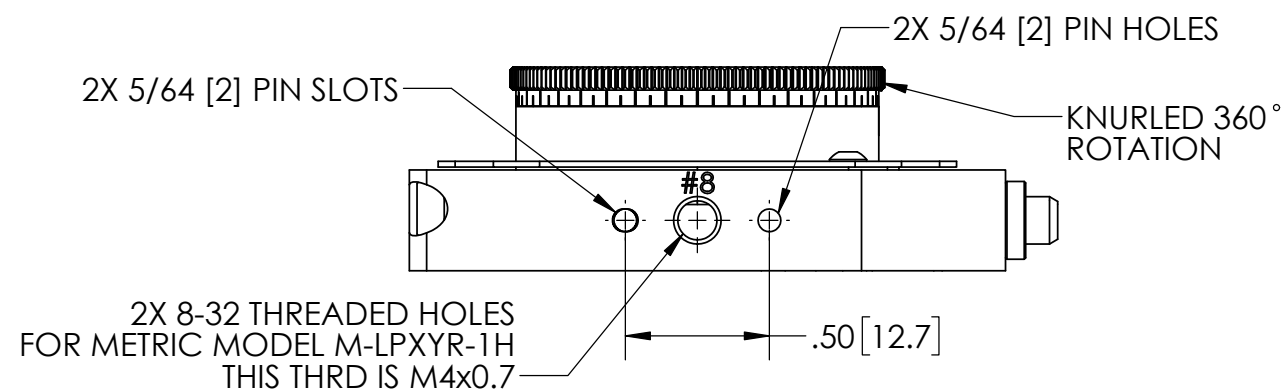
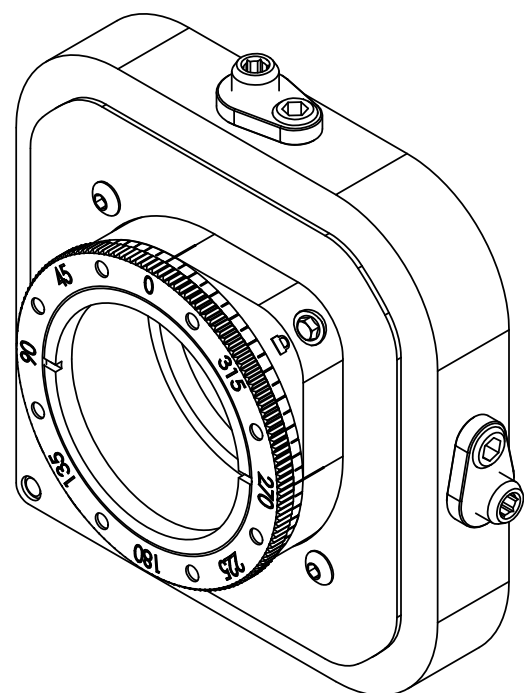


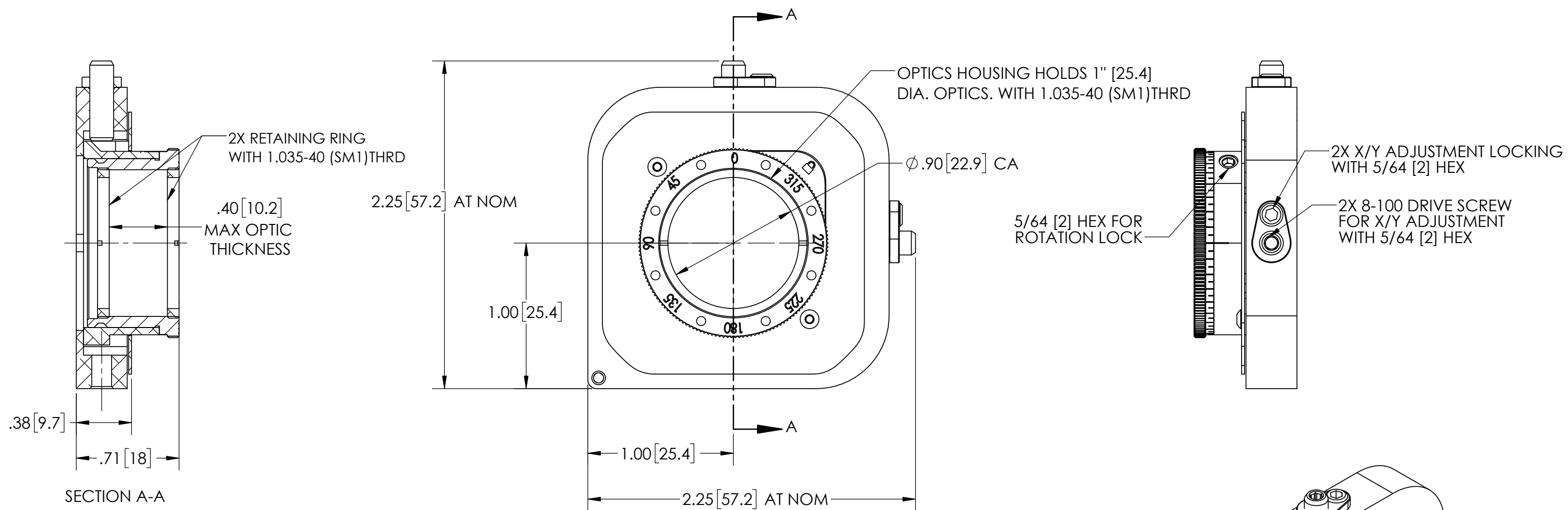

TECH SPECS:

1. X / Y TRANSLATION: $\pm 1.6\text{mm}$ AT $254\mu\text{m/rev}$; $0.71\mu\text{m}$ SENSITIVITY
2. 360 DEGREE ROTATION
3. CLEAR APERTURE: $\phi .90 [22.9\text{mm}]$
4. OPTICS AXIS HEIGHT: $1.0 [25.4\text{mm}]$
5. MAX OPTICS EDGE THICKNESS: $0.40 [10.2\text{mm}]$

MODEL: LPXYR-1H & M-LPXYR-1H