


4 X 1/4-20 (M6) Counterbored  
 Ø .281 THRU ALL  
 ▭ Ø.44 ▽ .26

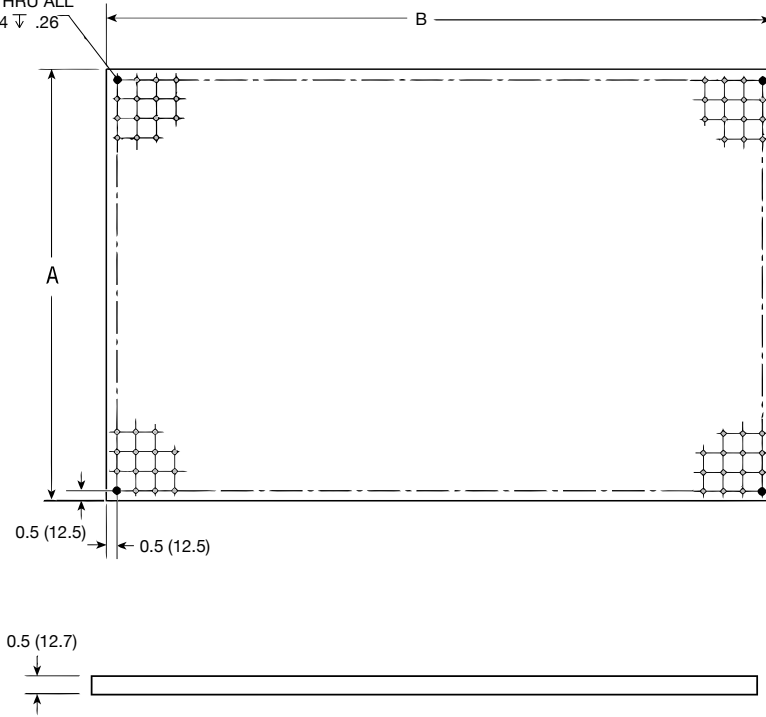

Model	A	B	Mounting Holes
M-SA2-06X06-LC	150 mm.	150 mm.	M6
M-SA2-08X08-LC	200 mm.	200 mm.	M6
M-SA2-08X10-LC	200 mm.	250 mm.	M6
M-SA2-11-LC	300 mm.	300 mm.	M6
M-SA2-12-LC	300 mm.	600 mm.	M6
M-SA2-12X18-LC	300 mm.	450 mm.	M6
M-SA2-13-LC	300 mm.	900 mm.	M6
M-SA2-18X18-LC	450 mm.	450 mm.	M6
M-SA2-18X24-LC	450 mm.	600 mm.	M6
M-SA2-18X30-LC	450 mm.	750 mm.	M6
M-SA2-22-LC	600 mm.	600 mm.	M6
M-SA2-23-LC	600 mm.	900 mm.	M6
M-SA2-30X30-LC	600 mm.	600 mm.	M6
SA2-06x06-LC	6 in.	6 in.	1/4-20
SA2-08X08-LC	8 in.	8 in.	1/4-20
SA2-08X10-LC	8 in.	10 in.	1/4-20
SA2-11-LC	12 in.	12 in.	1/4-20
SA2-12-LC	12 in.	24 in.	1/4-20
SA2-12X18-LC	12 in.	18 in.	1/4-20
SA2-13-LC	12 in.	36 in.	1/4-20
SA2-18X18-LC	18 in.	18 in.	1/4-20
SA2-18X24-LC	18 in.	24 in.	1/4-20
SA2-18X30-LC	18 in.	30 in.	1/4-20
SA2-22-LC	24 in.	24 in.	1/4-20
SA2-23-LC	24 in.	36 in.	1/4-20
SA2-30X30-LC	30 in.	30 in.	1/4-20