


SINGLE BRANCH LIQUID LIGHT GUIDE

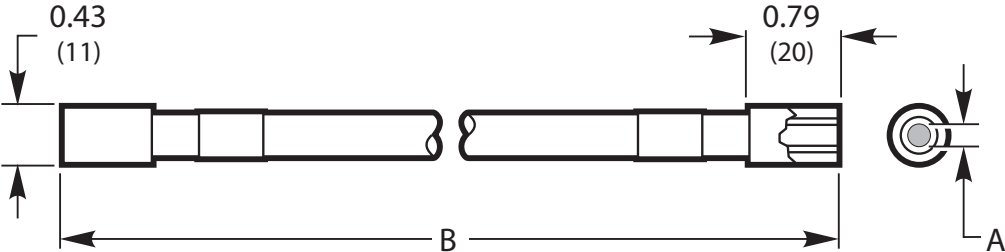

Core Diameter (A) inch (mm)	Total Length (B) inch (m)	Numerical Aperture	F/#	Acceptance Cone, 2a (degrees)	Min. Bend Radius inch (mm)	Model No.
UV-VIS Liquid Light Guides (300 to 650 nm)						
0.12 (3)	39.4 (1)	0.59	0.85	72	1.6 (40)	77554
0.12 (3)	79.0 (2)	0.59	0.85	72	1.6 (40)	77555
0.2 (5)	39.4 (1)	0.59	0.85	72	2.4 (60)	77556
0.2 (5)	79.0 (2)	0.59	0.85	72	2.4 (60)	77557
0.3 (8)	39.4 (1)	0.59	0.85	72	3.9 (100)	77628
0.3 (8)	79.0 (2)	0.59	0.85	72	3.9 (100)	77629
VIS Liquid Light Guides (340 to 800 nm)						
0.12 (3)	39.4 (1)	0.59	0.85	72	1.6 (40)	77566
0.12 (3)	79.0 (2)	0.59	0.85	72	1.6 (40)	77567
0.2 (5)	39.4 (1)	0.59	0.85	72	2.4 (60)	77568
0.2 (5)	79.0 (2)	0.59	0.85	72	2.4 (60)	77569
0.3 (8)	39.4 (1)	0.59	0.85	72	3.9 (100)	77631
0.3 (8)	79.0 (2)	0.59	0.85	72	3.9 (100)	77632
VIS-NIR Liquid Light Guides (420 to 2000 nm)						
0.12 (3)	39.4 (1)	0.52	0.96	62	1.6 (40)	77634
0.12 (3)	79.0 (2)	0.52	0.96	62	1.6 (40)	77635
0.2 (5)	39.4 (1)	0.52	0.96	62	2.4 (60)	77636
0.2 (5)	79.0 (2)	0.52	0.96	62	2.4 (60)	77637
0.3 (8)	39.4 (1)	0.52	0.96	62	3.9 (100)	77638
0.3 (8)	79.0 (2)	0.52	0.96	62	3.9 (100)	77639

