
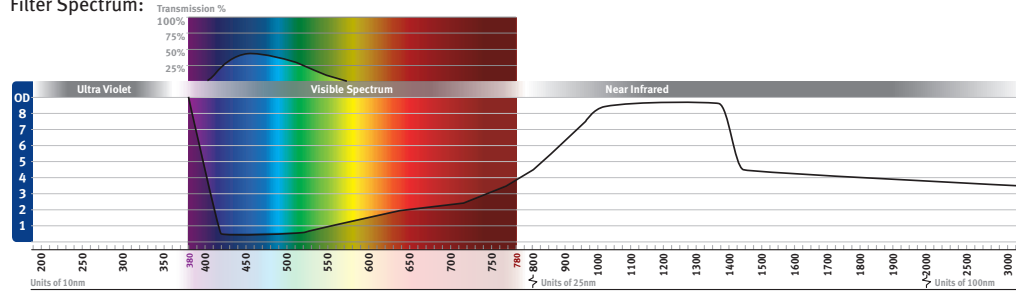




Filter	Filter Image	Optical Density Specifications	
P5P10		180 - 315 D LB10 + IR LB4 + M LB6 (OD 10+) >315 - 385 D LB6 + IRM LB8 (OD 8+) >385 - 400 DIRM LB4 (OD 4+) 730 - <770 DIRM LB2 (OD 2+) 770 - <800 DIRM LB3 (OD 3+) 800 - <840 DIRM LB4 (OD 4+) 840 - <880 DIRM LB5 (OD 5+) 880 - <960 DIRM LB6 (OD 6+) 960 - <1030 D LB6 + IRM LB7 (OD 7+) 1030 - 1400 D LB6 + IRM LB8 (OD 8+) >1400 - 3600 D LB3 + I LB4 (OD 4+) >1400 - 2000 R LB3 (OD 3+) >3600 - 4800 DI LB3 (OD 3+) >4800 - 11500 DI LB4 (OD4+) 640 - 700 RB1 0,01W 2x10E-6j (OD 1+) LV CE	
Material			Polycarbonate
Color			Blue
VLT			16%

Filter Spectrum:



Available Frame Styles for Filter: P5P10

CALL US FOR ADDITIONAL FRAME OPTIONS

		F18.P5P10.5000	
			
	F22.P5P10.5000		