
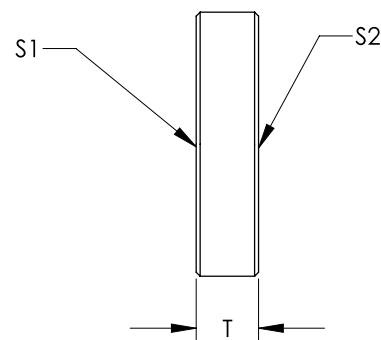


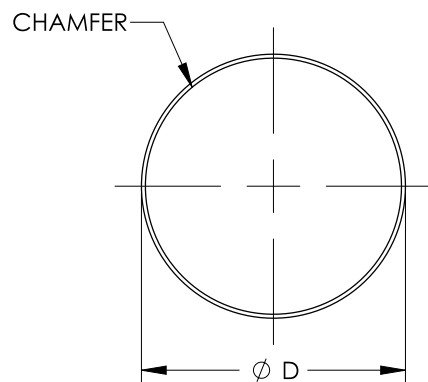

Model	Diameter	Thickness
05D20DM.10	12.7 mm	3.1 mm
05D20DM.11	12.7 mm	3.1 mm
05D20DM.4	12.7 mm	3.1 mm
05D20DM.5	12.7 mm	3.1 mm
05D20DM.8	12.7 mm	3.1 mm
05D20DM.6	12.7 mm	3.1 mm
07D20DM.11	19.05 mm	4.57 mm
07D20DM.4	19.05 mm	4.57 mm
07D20DM.5	19.05 mm	4.57 mm
07D20DM.8	19.05 mm	4.57 mm
07D20DM.10	19.05 mm	4.57 mm
07D20DM.6	19.05 mm	4.57 mm
10Z40DM.10	25.4 mm	6.0 mm
10Z20DM.10	25.4 mm	6.0 mm
10Z20DM.11	25.4 mm	6.0 mm
10Z20DM.4	25.4 mm	6.0 mm
10Z40DM.11	25.4 mm	6.0 mm
10Z40DM.4	25.4 mm	6.0 mm
10Z40DM.5	25.4 mm	6.0 mm
10Z40DM.8	25.4 mm	6.0 mm
10Z20DM.8	25.4 mm	6.0 mm
10D20DM.10	25.4 mm	6.0 mm
10D20DM.11	25.4 mm	6.0 mm
10D20DM.4	25.4 mm	6.0 mm
10D20DM.5	25.4 mm	6.0 mm
10D20DM.6	25.4 mm	6.0 mm
10D20DM.8	25.4 mm	6.0 mm
10D20RM.2	25.4 mm	6.0 mm

Model	Diameter	Thickness
3MD20DM.10	30.0 mm	6.0 mm
3MD20DM.4	30.0 mm	6.0 mm
3MD20DM.11	30.0 mm	6.0 mm
3MD20DM.5	30.0 mm	6.0 mm
20Z40DM.10	50.8 mm	12.7 mm
20Z40DM.11	50.8 mm	12.7 mm
20D20DM.10	50.8 mm	12.7 mm
20D20DM.11	50.8 mm	12.7 mm
20D20DM.4	50.8 mm	12.7 mm
20D20DM.6	50.8 mm	12.7 mm
20D20DM.8	50.8 mm	12.7 mm