
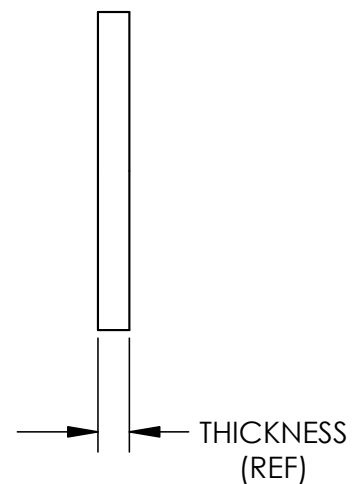


CLEAR APERTURE

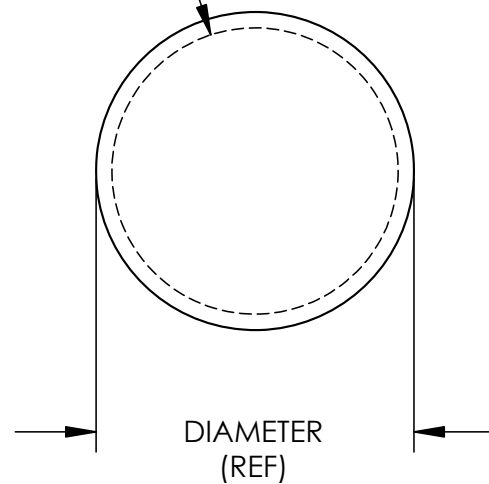

Model	Diameter	Thickness	CA
10QM20HM.15-G	25.4 mm	6.35 mm	20.32 mm
10QM20HM.35-G	25.4 mm	6.35 mm	20.32 mm
10QM20HM.45-G	25.4 mm	6.35 mm	20.32 mm
10QM20HM.75-G	25.4 mm	6.35 mm	20.32 mm
20QM20HM.15-G	50.8 mm	9.525 mm	40.64 mm
20QM20HM.35-G	50.8 mm	9.525 mm	40.64 mm
20QM20HM.45-G	50.8 mm	9.525 mm	40.64 mm
20QM20HM.75-G	50.8 mm	9.525 mm	40.64 mm