


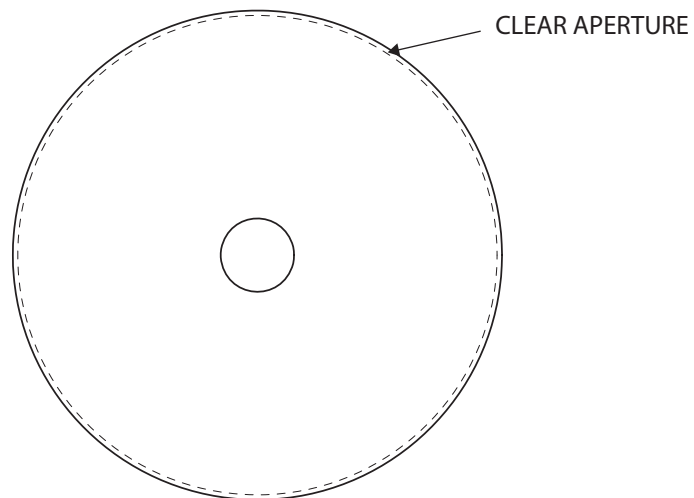

Model	Outer Diameter (mm)	Inner Diameter (mm)	Thickness (mm)	Clear Aperture (mm)
100FS01DV.1	100	7.5	2	98
100FS02DV.2	100	7.5	2	98
100FS04DV.4	100	7.5	2	98
25FS01DV.1	25	7.5	2	23
25FS02DV.2	25	7.5	2	23
25FS04DV.4	25	7.5	2	23
50FS01DV.1	50	7.5	2	48
50FS02DV.2	50	7.5	2	48
50FS04DV.4	50	7.5	2	48